


ECN/PCN No.: 4327

For Manufacturer			
Product Description: Oven Controlled Crystal Oscillator	Abracon Part Number / Part Series: AOCJY	☐ Documentation only ☒ ECN ☐ EOL	☒ Series ☐ Part Number
Affected Revision: H	New Revision: I	Application:	☐ Safety ☒ Non-Safety

Prior to Change:

Part Number Builder:


-Packaging for Bulk product= Tray

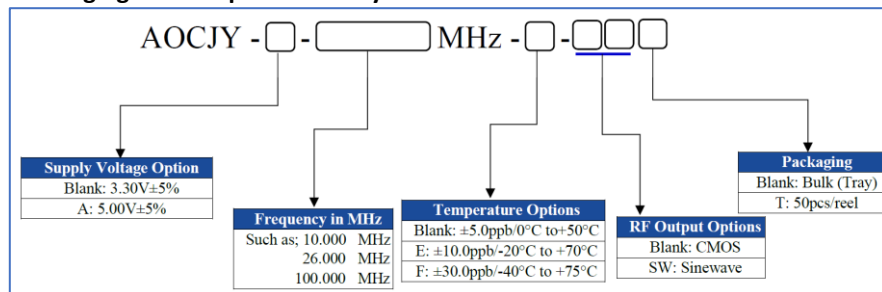

After Change:

Part Number Builder:

-Packaging for Bulk product= Tray or Cut/Tape

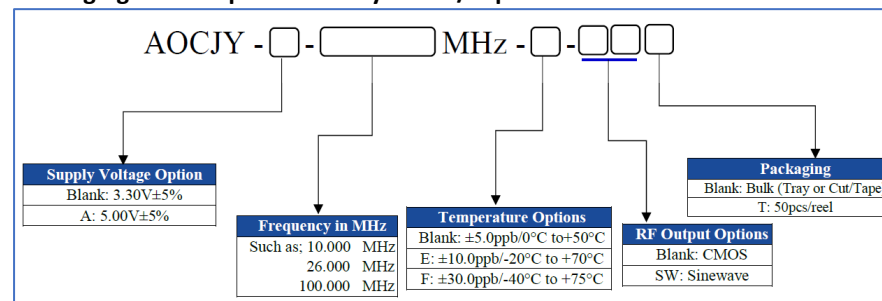

Cause/Reason for Change:

Standard product series review and upgrade. Updated packing method for higher volume quantities.

Change Plan		
Effective Date: 06/24/2022	Additional Remarks: N/A	
Change Declaration: This change does not affect the electrical nor mechanical performance of this product.		
Issued Date: 06/24/2022	Issued By: Brooke Cushman Product Engineer	Issued Department: Engineering
Approval: Thomas Culhane Engineering Director	Approval: Reuben Quintanilla Quality Director	Approval: Ying Huang Purchasing Director

For Abracon EOL only		
Last Time Buy (if applicable): N/A		Alternate Part Number / Part Series: N/A
Additional Approval: N/A	Additional Approval: N/A	Additional Approval: N/A
Customer Approval (If Applicable)		
Qualification Status: ☐ Approved ☐ Not accepted <i>Note: It is considered approved if there is no feedback from the customer 1 month after ECN/PCN is released.</i>		
Customer Part Number:		Customer Project:
Company Name:	Company Representative:	Representative Signature:
Customer Remarks:		

brand	affected part numbers
abracon	AOCJY-10.000MHZ
abracon	AOCJY-10.000MHZ-E
abracon	AOCJY-10.000MHZ-E-SW
abracon	AOCJY-10.000MHZ-F
abracon	AOCJY-10.000MHZ-F-SW
abracon	AOCJY-100.000MHZ
abracon	AOCJY-100.000MHZ-E
abracon	AOCJY-100.000MHZ-E-SW
abracon	AOCJY-100.000MHZ-F
abracon	AOCJY-100.000MHZ-F-SW
abracon	AOCJY-100.000MHZ-SW
abracon	AOCJY-107-40.000MHZ-T
abracon	AOCJY-12.800MHZ
abracon	AOCJY-12.800MHZ-E
abracon	AOCJY-12.800MHZ-F
abracon	AOCJY-16.368MHZ-F-SW
abracon	AOCJY-16.384MHZ
abracon	AOCJY-16.384MHZ-E
abracon	AOCJY-16.384MHZ-F-SW
abracon	AOCJY-19.440MHZ-E
abracon	AOCJY-20.000MHZ
abracon	AOCJY-20.000MHZ-E
abracon	AOCJY-20.000MHZ-F
abracon	AOCJY-20.000MHZ-SW
abracon	AOCJY-26.000MHZ-E-SW
abracon	AOCJY-26.000MHZ-F
abracon	AOCJY-26.000MHZ-SW
abracon	AOCJY-38.400MHZ-E
abracon	AOCJY-38.880MHZ
abracon	AOCJY-38.880MHZ-E
abracon	AOCJY-38.880MHZ-F
abracon	AOCJY-40.000MHZ-E
abracon	AOCJY-40.000MHZ-E-SW
abracon	AOCJY-96.000MHZ
abracon	AOCJY-96.000MHZ-E