

PRODUCT CHANGE NOTIFICATION (PCN)

ISSUE DATE: 22/8/2022
MODIFICATION / REVISION DATE: 22/8/2022

A-MCSP60050 MODULAR CABLE

CHANGE NOTIFICATION:

PCN 20220822_A-MCSP60050

DESCRIPTION OF CHANGES:

CHANGE OF DATA SHEET
CHANGE OF DATA SHEET
New Draw.-No. ASS_7542_CArev06

REASON FOR CHANGE:

CHANGE OF MATERIAL PARAMETERS OR PROPERTIES
CHANGE OF MATERIAL PARAMETERS OR PROPERTIES

KEY CHARACTERISTICS OF CHANGE:

Details see page 3

PRODUCTS AFFECTED:

A-MCSP60050

DATE OF CHANGE AND IMPLEMENTATION:

CHANGE: WEEK 35 / YEAR 2022
IMPLEMENTATION: 22/8/2022

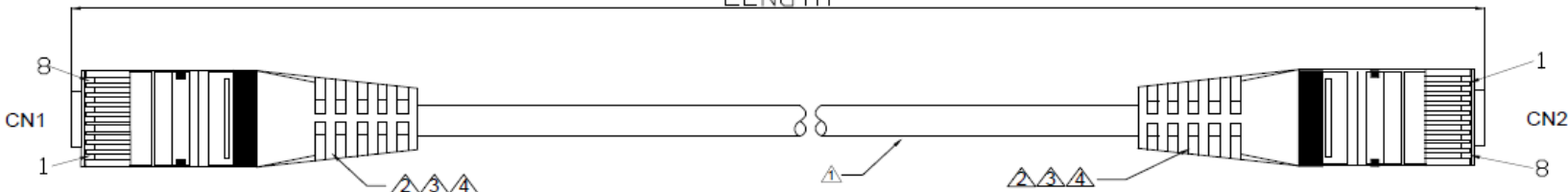
RESPONSE:

NO RESPONSE TO THIS NOTIFICATION IS REQUIRED

PRODUCT CHANGE NOTIFICATION (PCN)

ISSUE DATE: 22/8/2022
MODIFICATION / REVISION DATE: 22/8/2022

A-MCSP60050	OLD VERSION	A-MCSP60050	NEW VERSION																																																																																										
PIN OUT		PIN OUT																																																																																											
PIN OUT <table><tr><th>CN1</th><th>④ WIRE COLOR</th><th>CN2</th></tr><tr><td>1</td><td>ORANGE/WHITE</td><td>1</td></tr><tr><td>2</td><td>ORANGE</td><td>2</td></tr><tr><td>3</td><td>GREEN/WHITE</td><td>3</td></tr><tr><td>6</td><td>GREEN</td><td>6</td></tr><tr><td>4</td><td>BLUE</td><td>4</td></tr><tr><td>5</td><td>BLUE/WHITE</td><td>5</td></tr><tr><td>7</td><td>BROWN/WHITE</td><td>7</td></tr><tr><td>8</td><td>BROWN</td><td>8</td></tr><tr><td>SHELL</td><td>BRAID</td><td>SHELL</td></tr></table>		CN1	④ WIRE COLOR	CN2	1	ORANGE/WHITE	1	2	ORANGE	2	3	GREEN/WHITE	3	6	GREEN	6	4	BLUE	4	5	BLUE/WHITE	5	7	BROWN/WHITE	7	8	BROWN	8	SHELL	BRAID	SHELL	PIN OUT <table><tr><th>CN1</th><th>WIRE COLOR</th><th>CN2</th></tr><tr><td>1</td><td>WHITE</td><td>1</td></tr><tr><td>2</td><td>ORANGE</td><td>2</td></tr><tr><td>3</td><td>WHITE</td><td>3</td></tr><tr><td>6</td><td>GREEN</td><td>6</td></tr><tr><td>4</td><td>BLUE</td><td>4</td></tr><tr><td>5</td><td>WHITE</td><td>5</td></tr><tr><td>7</td><td>WHITE</td><td>7</td></tr><tr><td>8</td><td>BROWN</td><td>8</td></tr><tr><td>SHELL</td><td>BRAID</td><td>SHELL</td></tr></table> ⑥ *The PIN OUT is applied to cable length ≥10M PIN OUT <table><tr><th>CN1</th><th>WIRE COLOR</th><th>CN2</th></tr><tr><td>1</td><td>ORANGE/WHITE</td><td>1</td></tr><tr><td>2</td><td>ORANGE</td><td>2</td></tr><tr><td>3</td><td>GREEN/WHITE</td><td>3</td></tr><tr><td>6</td><td>GREEN</td><td>6</td></tr><tr><td>4</td><td>BLUE</td><td>4</td></tr><tr><td>5</td><td>BLUE/WHITE</td><td>5</td></tr><tr><td>7</td><td>BROWN/WHITE</td><td>7</td></tr><tr><td>8</td><td>BROWN</td><td>8</td></tr><tr><td>SHELL</td><td>BRAID</td><td>SHELL</td></tr></table> *The PIN OUT is applied to cable length <10M		CN1	WIRE COLOR	CN2	1	WHITE	1	2	ORANGE	2	3	WHITE	3	6	GREEN	6	4	BLUE	4	5	WHITE	5	7	WHITE	7	8	BROWN	8	SHELL	BRAID	SHELL	CN1	WIRE COLOR	CN2	1	ORANGE/WHITE	1	2	ORANGE	2	3	GREEN/WHITE	3	6	GREEN	6	4	BLUE	4	5	BLUE/WHITE	5	7	BROWN/WHITE	7	8	BROWN	8	SHELL	BRAID	SHELL
CN1	④ WIRE COLOR	CN2																																																																																											
1	ORANGE/WHITE	1																																																																																											
2	ORANGE	2																																																																																											
3	GREEN/WHITE	3																																																																																											
6	GREEN	6																																																																																											
4	BLUE	4																																																																																											
5	BLUE/WHITE	5																																																																																											
7	BROWN/WHITE	7																																																																																											
8	BROWN	8																																																																																											
SHELL	BRAID	SHELL																																																																																											
CN1	WIRE COLOR	CN2																																																																																											
1	WHITE	1																																																																																											
2	ORANGE	2																																																																																											
3	WHITE	3																																																																																											
6	GREEN	6																																																																																											
4	BLUE	4																																																																																											
5	WHITE	5																																																																																											
7	WHITE	7																																																																																											
8	BROWN	8																																																																																											
SHELL	BRAID	SHELL																																																																																											
CN1	WIRE COLOR	CN2																																																																																											
1	ORANGE/WHITE	1																																																																																											
2	ORANGE	2																																																																																											
3	GREEN/WHITE	3																																																																																											
6	GREEN	6																																																																																											
4	BLUE	4																																																																																											
5	BLUE/WHITE	5																																																																																											
7	BROWN/WHITE	7																																																																																											
8	BROWN	8																																																																																											
SHELL	BRAID	SHELL																																																																																											
FOR DETAIL, PLEASE TAKE ATTACHED NEW DRAWING: FOR REFERENCE																																																																																													

	1	2	3	4	5	6	7																																																																																								
A	LENGTH 							A																																																																																							
B								B																																																																																							
C	① Order code:A-MCSP60XXX : color Grey order lengths in meter: 0.5,1,2,3,5,7,10,15,20,30 ① Order code:A-MCSP60XXX/X order lengths in meter: 0.5,1,2,3,5,7,10,15,20,30 order color: (R)Red,(Y)Yellow, (G)Green,(B)Blue ② Tolerance <table><tr><th>Length Code</th><th>Length(meter)</th><th>Max-M</th><th>Min-M</th></tr><tr><td>005</td><td>0.5</td><td>+0.03</td><td>-0.025</td></tr><tr><td>010</td><td>1</td><td>+0.04</td><td>-0.035</td></tr><tr><td>020</td><td>2</td><td>+0.06</td><td>-0.06</td></tr><tr><td>030</td><td>3</td><td>+0.09</td><td>-0.09</td></tr><tr><td>050</td><td>5</td><td>+0.15</td><td>-0.15</td></tr><tr><td>070</td><td>7</td><td>+0.21</td><td>-0.21</td></tr><tr><td>100</td><td>10</td><td>+0.3</td><td>-0.3</td></tr><tr><td>150</td><td>15</td><td>+0.45</td><td>-0.45</td></tr><tr><td>200</td><td>20</td><td>+0.6</td><td>-0.6</td></tr><tr><td>300</td><td>30</td><td>+0.9</td><td>-0.9</td></tr></table> ⑤ <table><tr><th>Length Code</th><th>Length(meter)</th><th>Max-M</th><th>Min-M</th></tr><tr><td>005</td><td>0.5</td><td>+0.03</td><td>-0.025</td></tr><tr><td>010</td><td>1</td><td>+0.04</td><td>-0.035</td></tr><tr><td>020</td><td>2</td><td>+0.06</td><td>-0.06</td></tr><tr><td>030</td><td>3</td><td>+0.09</td><td>-0.09</td></tr><tr><td>050</td><td>5</td><td>+0.15</td><td>-0.15</td></tr><tr><td>070</td><td>7</td><td>+0.21</td><td>-0.21</td></tr><tr><td>100</td><td>10</td><td>+0.3</td><td>-0.3</td></tr><tr><td>150</td><td>15</td><td>+0.45</td><td>-0.45</td></tr><tr><td>200</td><td>20</td><td>+0.6</td><td>-0.6</td></tr><tr><td>300</td><td>30</td><td>+0.9</td><td>-0.9</td></tr></table> ④ ④							Length Code	Length(meter)	Max-M	Min-M	005	0.5	+0.03	-0.025	010	1	+0.04	-0.035	020	2	+0.06	-0.06	030	3	+0.09	-0.09	050	5	+0.15	-0.15	070	7	+0.21	-0.21	100	10	+0.3	-0.3	150	15	+0.45	-0.45	200	20	+0.6	-0.6	300	30	+0.9	-0.9	Length Code	Length(meter)	Max-M	Min-M	005	0.5	+0.03	-0.025	010	1	+0.04	-0.035	020	2	+0.06	-0.06	030	3	+0.09	-0.09	050	5	+0.15	-0.15	070	7	+0.21	-0.21	100	10	+0.3	-0.3	150	15	+0.45	-0.45	200	20	+0.6	-0.6	300	30	+0.9	-0.9
Length Code	Length(meter)	Max-M	Min-M																																																																																												
005	0.5	+0.03	-0.025																																																																																												
010	1	+0.04	-0.035																																																																																												
020	2	+0.06	-0.06																																																																																												
030	3	+0.09	-0.09																																																																																												
050	5	+0.15	-0.15																																																																																												
070	7	+0.21	-0.21																																																																																												
100	10	+0.3	-0.3																																																																																												
150	15	+0.45	-0.45																																																																																												
200	20	+0.6	-0.6																																																																																												
300	30	+0.9	-0.9																																																																																												
Length Code	Length(meter)	Max-M	Min-M																																																																																												
005	0.5	+0.03	-0.025																																																																																												
010	1	+0.04	-0.035																																																																																												
020	2	+0.06	-0.06																																																																																												
030	3	+0.09	-0.09																																																																																												
050	5	+0.15	-0.15																																																																																												
070	7	+0.21	-0.21																																																																																												
100	10	+0.3	-0.3																																																																																												
150	15	+0.45	-0.45																																																																																												
200	20	+0.6	-0.6																																																																																												
300	30	+0.9	-0.9																																																																																												